


Kodiak Positive Displacement Pumps

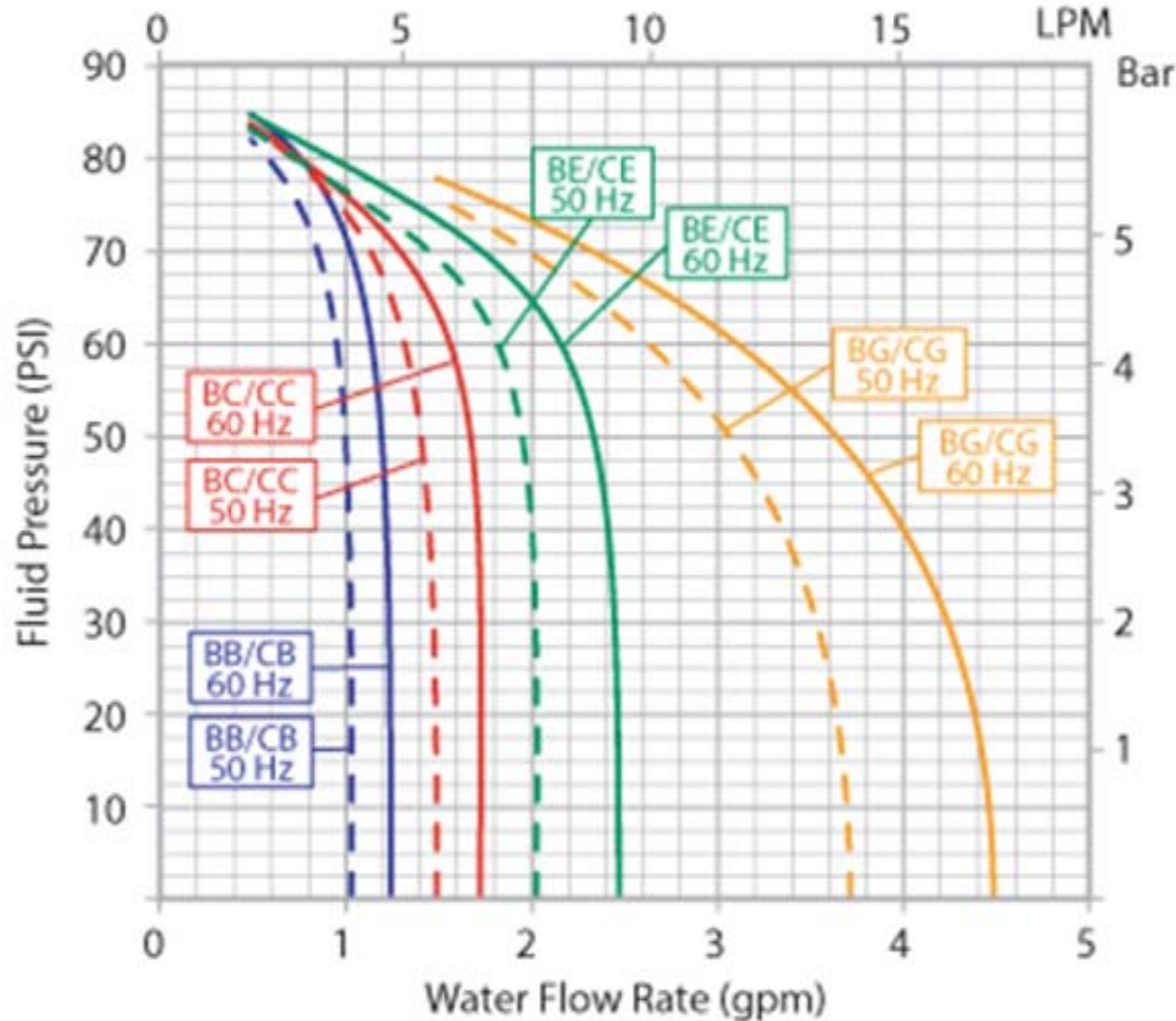

- BB: Brass, 1.3 gpm (4.9 lpm)
- CB: Stainless Steel 1.3 gpm (4.9 lpm)

- BC: Brass, 1.8 gpm (6.8 lpm)
- CC: Stainless Steel 1.8 gpm (6.8 lpm)

- BE: Brass, 2.3 gpm (8.7 lpm)
- CE: Stainless Steel 2.3 gpm (8.7 lpm)

- BG: Brass, 4.3 gpm (16.3 lpm)
- CG: Stainless Steel 4.3 gpm (16.3 lpm)

Pressure relief is factory set a 90 psi (6.2 bar). Other settings available on request.

BG/CG pumps can be operated at flow rates as low as 0.5 gpm (1.9 lpm) for the RC011 and RC022

Includes pressure drop through chiller