
 
 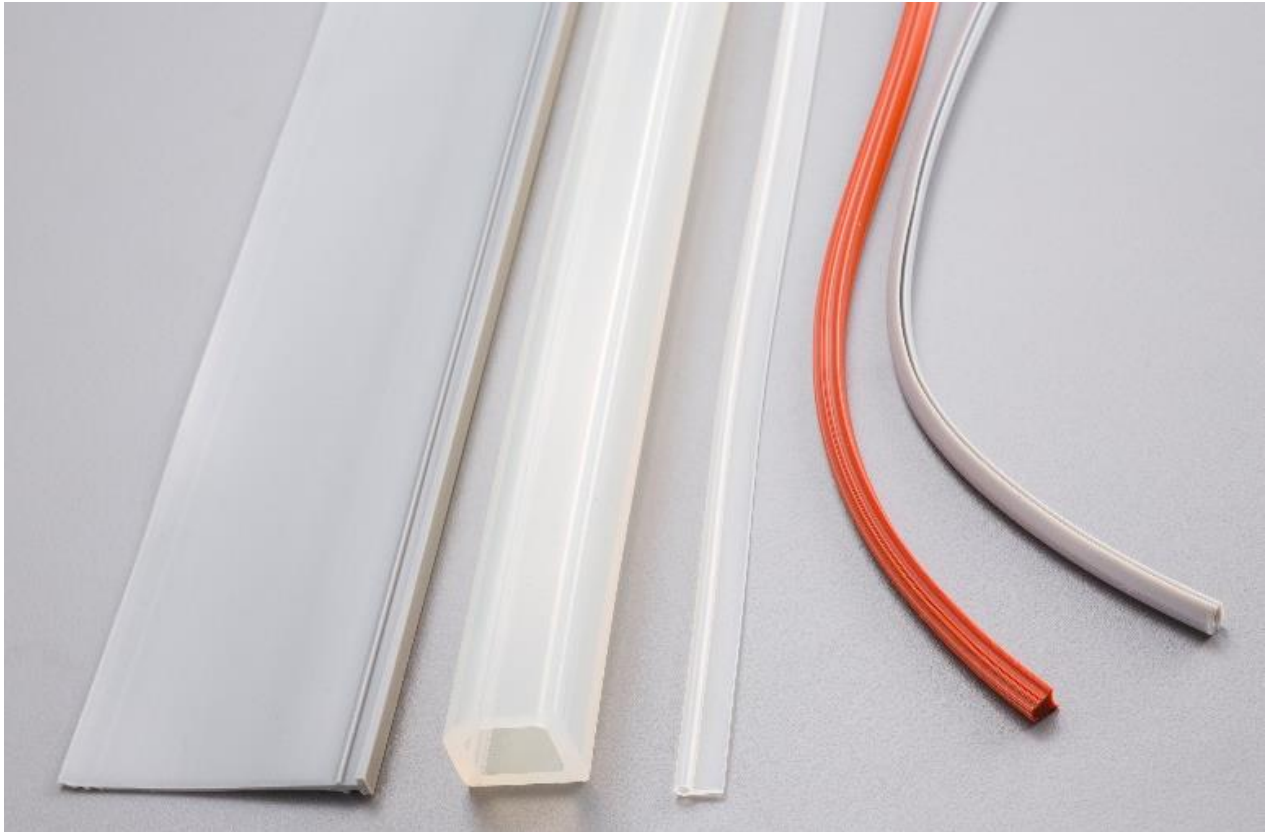


Silicone – profiles – tubes – cords - bands



 
Dimensions:

Smallest dimensions:
(mm)



or on request

Largest dimensions:
(mm)



or on request

Weight: min. 2.5 g/m
max. 1200 g/m

Tolerances:

E2 DIN ISO 3302-1
other tolerances upon request

Quality:

Hardness: 20° up to 85° Shore A DIN 53505
Temperature stability: - 60° C up to + 250° C
Special qualities up to + 300° C

Delivery units:

Production lengths 25/50 m
packed in polybags

Colours:

translucent or other colours on arrangement

Miscellaneous:

Vulcanised joints and frames

In-house tool manufacturing for extrusion

Issue 09/2023

This document is not subject to updates.