


Silicone profiles – construction industry




Application:

Sealing of windows
Sealing of doors and frames
Sealing of glazing
Sealing of facade elements

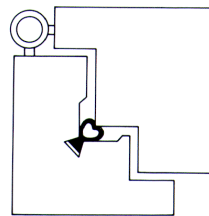

doorframes

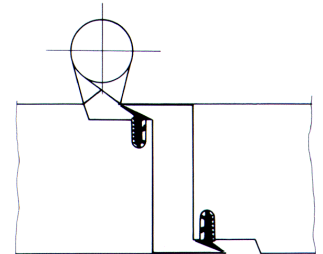

windows

Quality:

Technical standard quality
Hardness: 20° Shore up to 85° Shore A
DIN 53505

Tolerances:

E2 DIN ISO 3302-1
other tolerances upon request

Weight: min. 2.5 g/m
max. 1200 g/m

Colours:

translucent or other colours on arrangement

Delivery units:

Delivery units are 25 and 50 meters
packed in polybags.
100 meters are available
packed loose in cardboard boxes.
Profiles can be delivered talcum powdered.